


## Sealing ring ▶ Aluminum



00127843

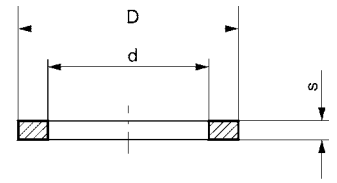

00108760

Part No.	G	d	D	s	Delivery quantity [Piece]	Working pressure min./max. [bar]	Ambient temperature min./max. [C°]		
<b>1820209011</b>	M5	5.2	7.4	1	100	-0.95 / 15	-20 / +100		
<b>1820209000</b>	G1/8	10.2	13.4	1	100	-0.95 / 15	-20 / +100		
<b>1820209001</b>	G1/4	14.2	17.9	1.5	100	-0.95 / 15	-20 / +100		
<b>1820209002</b>	G3/8	17.2	20.9	1.5	100	-0.95 / 15	-20 / +100		
<b>1820209003</b>	G1/2	21.2	25.9	1.5	100	-0.95 / 15	-20 / +100		
<b>1820209006</b>	G3/4	27.3	31.9	2	50	-0.95 / 15	-20 / +100		
1820209008	G1	33.3	38.9	2	50	-0.95 / 15	-20 / +100		

Sealing ring, form A DIN 7603  
G = thread size