

Pneumatic connection technologies ▶ Push-In fittings

Series QR1-S standard

▶ Blanking plug ▶ pin bushing ▶ Ø 4 - Ø16 ▶ QR1-S-RBS



00136364

Ambient temperature min./max.
Working pressure min./max.

+0 °C / +60 °C
-0.95 bar / 10 bar


Materials:
Screw
Housing

nickel-plated
Polybutyleneterephthalate

Technical Remarks

- The series QR1 (plastic) and QR2 (metal) can not be combined
- For further information about assembling and tolerances of adaptable tubing, see the section "Technical information".

Dimensions

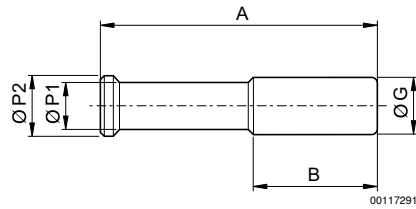

Part No.	Port G	A	B	Ø P1	Ø P2	Delivery quantity [Piece]	Weight [kg]				
2123204000	Ø 4	28	16	3	4	20	0.0004				
2123206000	Ø 6	32	17	4	6	20	0.0007				
2123208000	Ø 8	39	18.5	5	8	20	0.0014				
2123210000	Ø 10	42	21	8	10	20	0.002				
2123212000	Ø 12	44	22.5	8	12	20	0.0036				
2123214000	Ø 14	45	24.6	8	14	10	0.005				
R412005331	Ø16	46	24.8	10	16	10	0.004				