

Pneumatic connection technologies ▶ Supplementary products

T-union

▶ internal thread, 3x ▶ G 1/8 - G 1 ▶ FPT-S-RTK



00110658


Ambient temperature min./max.
Working pressure min./max.

-20°C / +80°C
0 bar / 16 bar

Materials:
Screw
Housing
Thread

Brass, nickel-plated
Brass, nickel-plated
Brass, nickel-plated

Dimensions

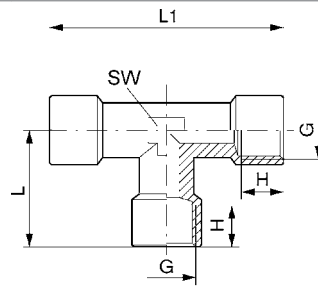

00107926

Part No.	Port G	H	L	L1	SW	Delivery quantity [Piece]						
1823391739	G 1/8	8	21	42	10	10						
1823391740	G 1/4	11	25.5	51	13	10						
1823391741	G 3/8	11.5	28	56	17	5						
1823391742	G 1/2	15	33	67	21	5						
1823391743	G 3/4	16.5	36	73	25	2						
1823391744	G 1	19	45	90	36	2						